


64624473-24 | 6462 4 473-24

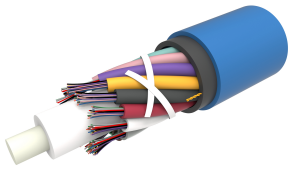

Outdoor Fiber Cable, 24-fiber, multimode, loose tube, blue

Product Classification

Regional Availability	Australia/New Zealand
Portfolio	CommScope®
Product Type	Fiber OSP cable
Product Series	O-LN

General Specifications

Cable Type	Loose tube
Subunit Type	Gel-filled
Jacket Color	Blue
Jacket Marking	Meters
Fibers per Subunit, quantity	24
Total Fiber Count	24

Dimensions

Diameter Over Jacket	8.9 mm 0.35 in
-----------------------------	------------------

Mechanical Specifications

Flex	25 cycles
-------------	-----------

Optical Specifications

Fiber Type	OM3
-------------------	-----

Optical Specifications, Wavelength Specific

Standards Compliance	TIA-492AAAC (OM3)
-----------------------------	-------------------

Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

