


MTC3619

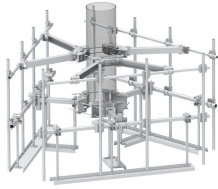

Monopole T-Frame kit with VSR Reinforcement and Work Platforms, 15 in to 50 in OD, 12 ft 6 in face, includes (12) 2-3/8in x 96in pipes

Product Classification

Product Type Monopole T-frame kit

General Specifications

Mounting Monopole, 381–1270 mm (15–50 in) OD

Pipe, quantity 12

Sectors, quantity 3

Dimensions

Height 2,438.4 mm | 96 in

Face Width 3.81 m | 12.5 ft

Width 3810 mm | 150 in

Pipe Length 2,438.4 mm | 96 in

Mounting Diameter, maximum 1270 mm | 50 in

Mounting Diameter, minimum 381 mm | 15 in

Pipe Outer Diameter 60.96 mm | 2.4 in

Stand-off Distance 914.4 mm | 36 in

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Cellular pipe frames | Pipe mounts | Platform | Ring mount | Stand-off arms

Packaging quantity 1

Weight, net 985.919 kg | 2,173.58 lb

