


TES-SS-MSK13 | UNIVERSAL CHANNEL CROSSOVER

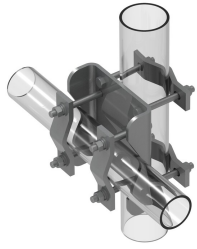

Universal Channel Crossover Plate, connects up to 4-1/2" OD x 3-1/2" OD Pipe
(Pipe not included)

Product Classification

Product Type Clamp plate

General Specifications

Mounting Crossover plate

Dimensions

Mounting Diameter 2, maximum 3.5 in | 88.9 mm

Mounting Diameter 2, minimum 1.66 in | 42.164 mm

Mounting Diameter, maximum 4.5 in | 114.3 mm

Mounting Diameter, minimum 1.66 in | 42.164 mm

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Clamps | Hardware | Plates

Packaging quantity 1

Weight, net 11.7 kg | 25.794 lb