


FD3-AC144J00TBBP2

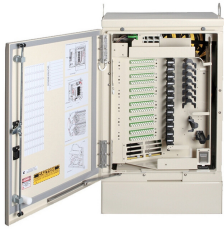

FDH 3000 Fiber Distribution Extra Small Pole Mount Cabinet, 72F, SC /APC, 0 splitters, die. LT, 96F stubs, 100 ft, 12F

Alternative products available:

FD3-AC144J00TBBP2-US FDH 3000 Fiber Distribution Extra Small Pole Mount Cabinet, 72F, SC/APC, 0 splitters, die. LT, 96F stubs, 100 ft, 12F, Build America Buy America (BABA)

Product Classification

| | |
|------------------------------|------------------------|
| Regional Availability | North America |
| Product Type | Fiber distribution hub |
| Product Series | FDH 3000 |

General Specifications

| | |
|--|-------------------------|
| Access | Front |
| Cable Type | Dry Dielectric - Ribbon |
| Color | Putty white |
| Distribution Cables, quantity | 1 |
| Distribution Ports, quantity | 144 |
| Fibers per Distribution Cable, quantity | 144 |
| Fibers per Feeder Cable, quantity | 24 |
| Interface, Input | SC |
| Interface Feature, Input | APC |
| Mounting | Pole |

Dimensions

| | |
|-----------------------|--------------------|
| Height | 762 mm 30 in |
| Width | 533 mm 20.984 in |
| Depth | 356 mm 14.016 in |
| Cable Length | 30.48 m 100 ft |
| Enclosure Size | Extra small |

FD3-AC144J00TBBP2

Material Specifications

| | |
|----------------------|---------------|
| Finish | Powder coated |
| Material Type | Steel |

Environmental Specifications

| | |
|----------------------------|--------|
| Environmental Space | Aerial |
|----------------------------|--------|

Packaging and Weights

| | |
|---------------------------|--------|
| Packaging quantity | 1 |
| Packaging Type | Pallet |

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|-----------------------------------|
| CHINA-ROHS | Above maximum concentration value |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |

