


# FTWLUCUCW6

---

## Base Product

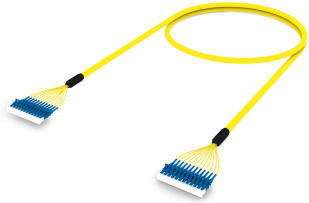

TeraSPEED® LC/UPC to LC/UPC, Distribution Cable, 6-Fiber, Plenum

## Product Classification

<b>Regional Availability</b>	North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber distribution cable assembly
<b>Product Brand</b>	SYSTIMAX InstaPATCH® 360
<b>Ordering Note</b>	For lengths greater than 999 ft (304 m), orders must be in meters

## General Specifications


<b>Cable Glands</b>	No glands
<b>Color, connector A</b>	Blue
<b>Color, connector B</b>	Blue
<b>Construction Type</b>	Armored
<b>Interface, Connector A</b>	LC/UPC
<b>Interface, Connector B</b>	LC/UPC
<b>Total Fibers, quantity</b>	6

## Dimensions

<b>Cable Assembly Length Range (m)</b>	3 – 305
<b>Cable Assembly Length Range (ft)</b>	7 – 999

## Ordering Tree

# FTWLCUCW6

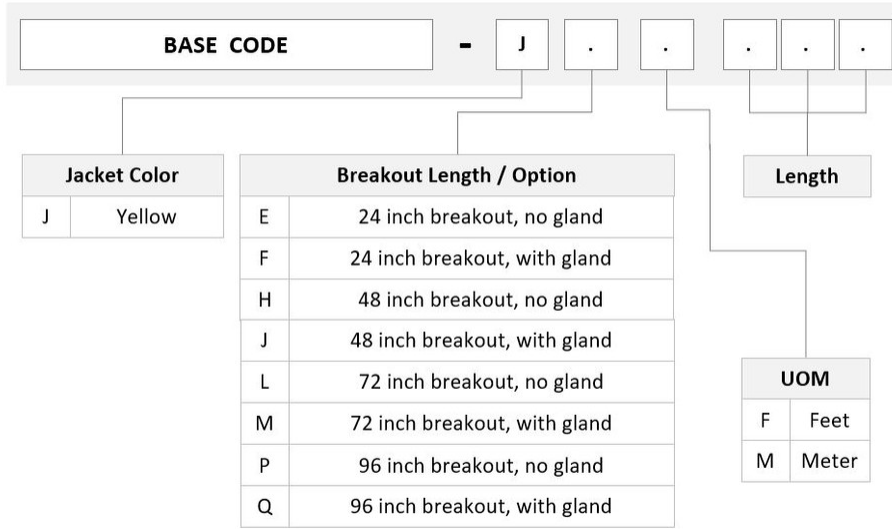

## Mechanical Specifications

**Cable Retention Strength, maximum** 0.50 lb @ 0° | 0.50 lb @ 90°

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.652.D | G.657.A1, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Plenum

## Regulatory Compliance/Certifications

### Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

UK-ROHS

### Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

Compliant

Compliant



# FTWLCUCW6

---

## Included Products

- 460125289 – Behind The Wall Pre-Radiused LC Connector for 0.9 mm Fiber, single-mode
- 760127795 – Fiber Indoor cable, TeraSPEED® Plenum Distribution, interlocking aluminum armored with plenum jacket, 6 fiber single-unit, Gel-free, Singlemode G.652.D and G.657.A1, Feet jacket marking, Yellow jacket color
- P-006-DZ-8W-FSUYL