

# UKXMPMPCD

## Base Product



Ultra Low Loss (ULL) OM4 MPO12 UPC (unpinned) to MPO12 UPC (unpinned) Fiber Trunk Cable Assembly, 12-Fiber, Armored Indoor Plenum

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications


<b>Connector A, quantity</b>	4
<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Lime green
<b>Connector B, quantity</b>	4
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Lime green
<b>Construction Type</b>	Armored   Stranded
<b>Furcation Color</b>	Lime green
<b>Interface, Connector A</b>	MPO-12/UPC Female
<b>Interface Feature, connector A</b>	Unpinned
<b>Interface, Connector B</b>	MPO-12/UPC Female
<b>Interface Feature, connector B</b>	Unpinned
<b>Jacket Color</b>	Lime green
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	12

## Dimensions

# UKXMPMPCD

**Cable Assembly Length Range (m)** 3 – 999  
**Cable Assembly Length Range (ft)** 10 – 999

## Ordering Tree

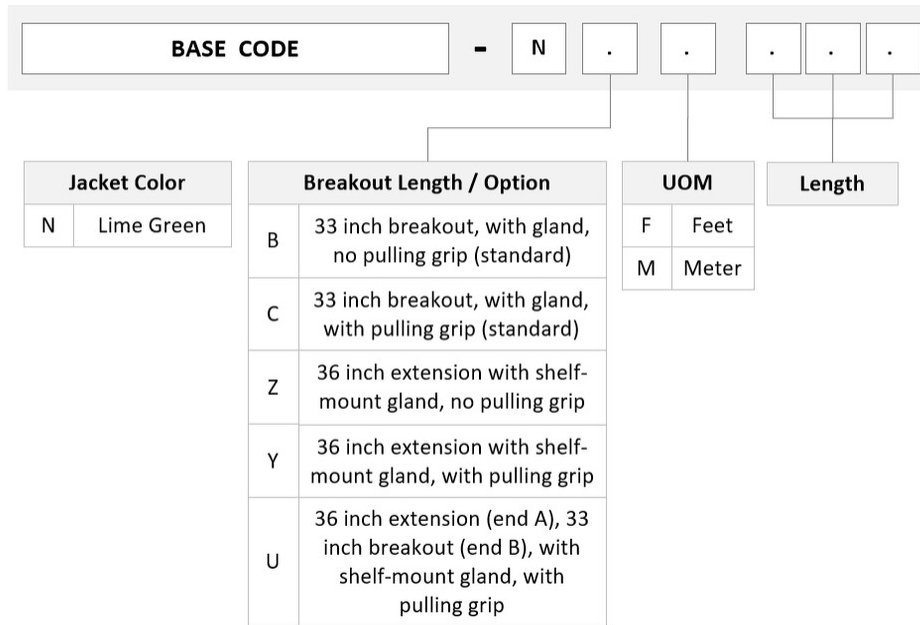

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode  
**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)  
**Environmental Space** Dual Rated LSZH/Riser

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted

# UKXMPMPCD

---

UK-ROHS

Compliant/Exempted

